

GF  
RUN  
STOP



0 1 2 3 4 5 6 7    0 1 2 3 4 5 6 7


CPU 226

0

EM231

AI 4x12 Bit

0 1 2 3 4

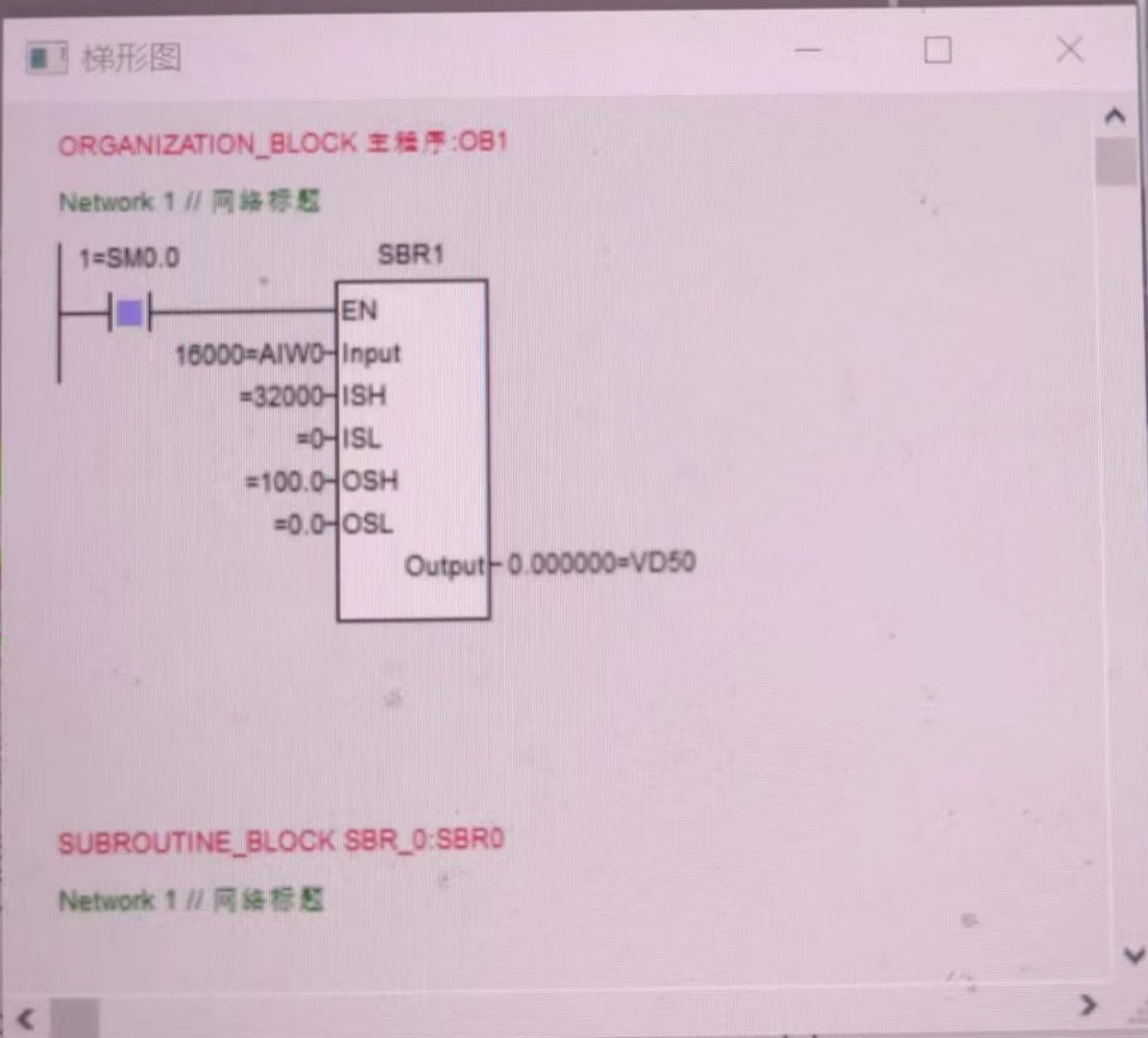

AI 0	9.77mA
AI 2	0.00mA
AI 4	0.00mA
AI 6	0.00mA

Conf. Module

PLS0

PLS1